 
 
 
 
 



sarlam

CHARTRES

NT 37 141/09

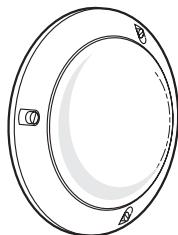

T1 Max.

75 W

75 W

 
 
 
 
60 W

75 W

T2 Max.

100 W

100 W








T1 Max.

9 W - 2 x 9 W - 13 W - 18 W - 21W - 9 + 9 W

T2 Max.


11W - 2 x 11W - 22W - 26W - 28W - 38W - 42 W - 11 W + 7 W - 11 W + 11W - 26 W + 13W - 26 W + 25W

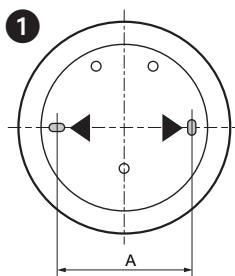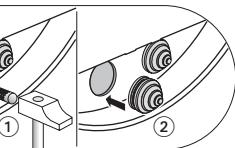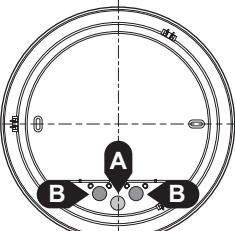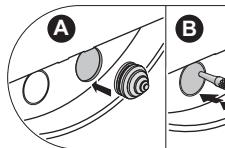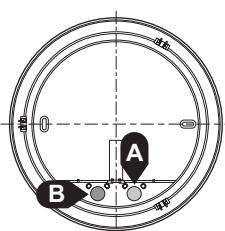


+





A : T 1 = 190 mm
 T 2 = 240 mm


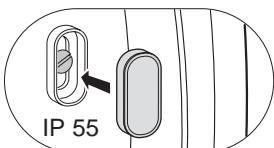


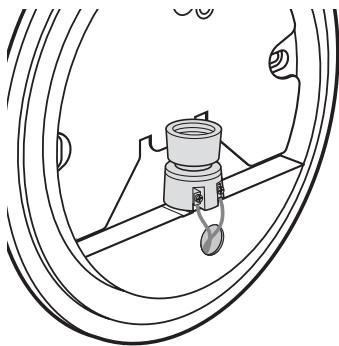

2

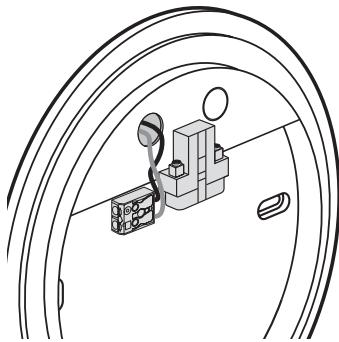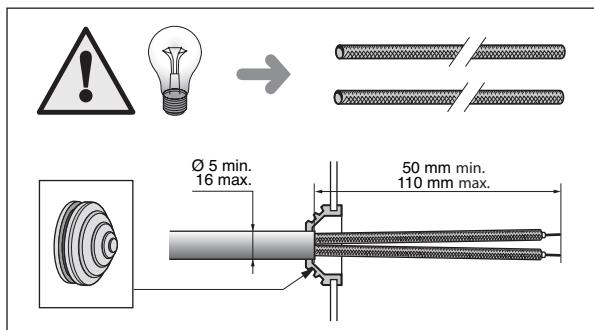


2

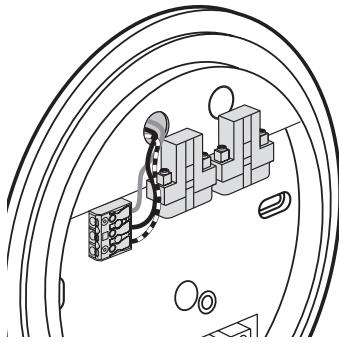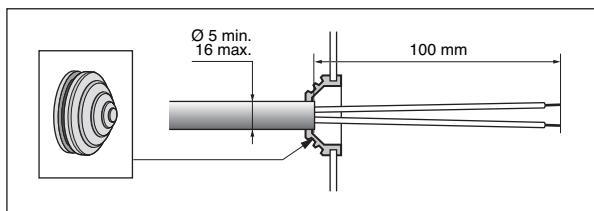


<input type="checkbox"/>	* CL. 1		T1	T2	
	 L1 + N	 L1 + N + L2	L1 9 W 2 x 9 W 13 W 16 W * 18 W 21 W *	11 W 2 x 11 W 22 W 26 W 28 W * 38 W * 42 W	
		 L1 + N + L2	L1 9 W + 9 W	11 W + 7 W	11 W + 11 W 26 W 13 W 25 W
			L2	*	*

3

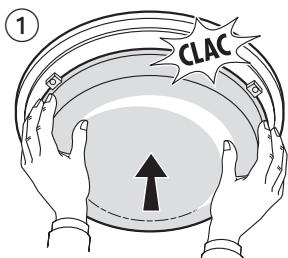

2

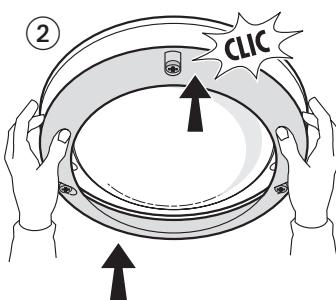

3

