 
 

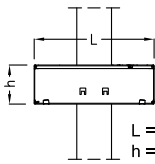
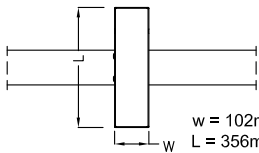
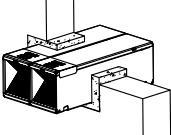
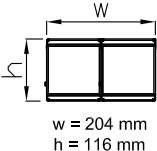
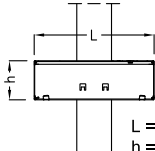
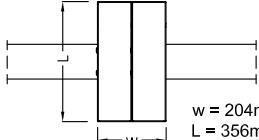
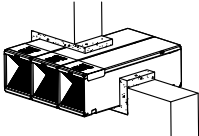
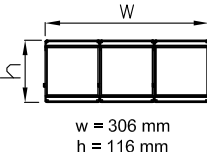
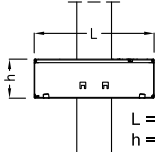
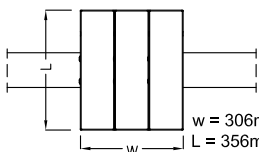
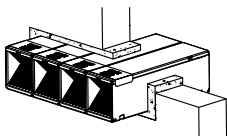
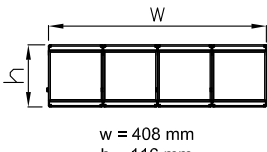
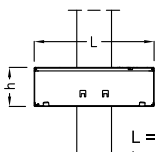
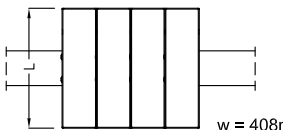
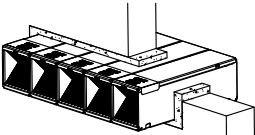
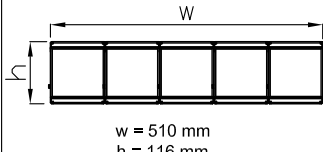
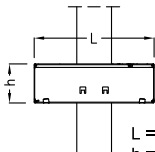
 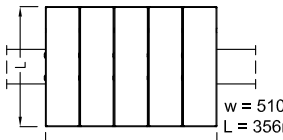
 

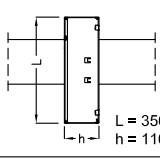
 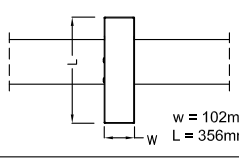
 

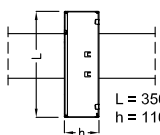
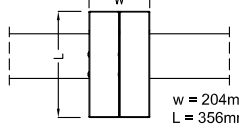
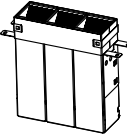
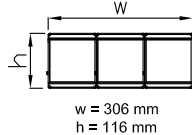
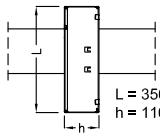
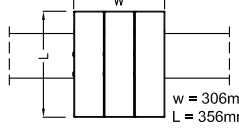
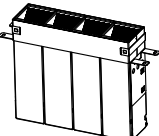
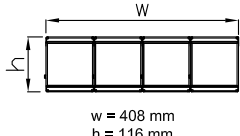
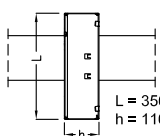
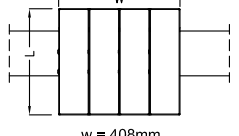
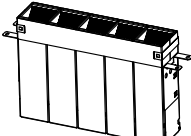
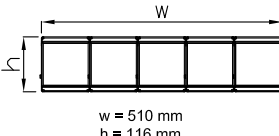
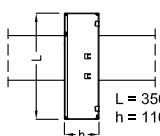
 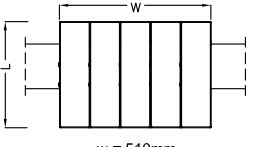
 

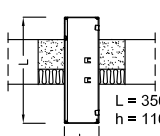
 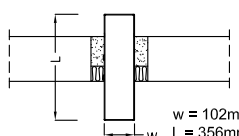
 

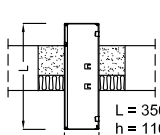
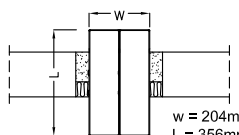
 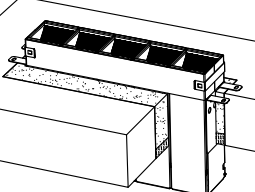

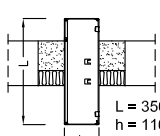
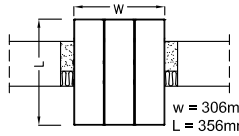
 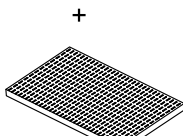

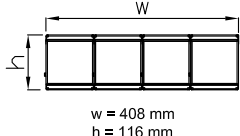
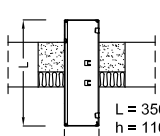




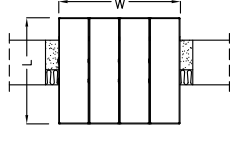


Seal Type	Number of Pathway(s) Series 33	System	Front view	Side view	Top view
<b>3</b>	1 x Module w = 102 mm h = 116 mm L = 356 mm		 w = 102 mm h = 116 mm	 L = 356mm h = 116	 w = 102mm L = 356mm
	2 x Modules w = 204 mm h = 116 mm L = 356 mm		 w = 204 mm h = 116 mm	 L = 356mm h = 116	 w = 204mm L = 356mm
	3 x Modules w = 306 mm h = 116 mm L = 356 mm		 w = 306 mm h = 116 mm	 L = 356mm h = 116	 w = 306mm L = 356mm
	4 x Modules w = 408 mm h = 116 mm L = 356 mm		 w = 408 mm h = 116 mm	 L = 356mm h = 116	 w = 408mm L = 356mm
	5 x Modules w = 510 mm h = 116 mm L = 356 mm		 w = 510 mm h = 116 mm	 L = 356mm h = 116	 w = 510mm L = 356mm

Seal Type	Number of Pathway(s) Series 33	System	Front view	Side view	Top view
4	1 x Module w = 102 mm h = 116 mm L = 356 mm		 w = 102 mm h = 116 mm	 L = 356 mm h = 116	 w = 102 mm L = 356 mm
	5	Plaquette peut etre ouverte pour cables deja installes 	 w = 102 mm h = 116 mm	 L = 356 mm h = 116	 w = 102 mm L = 356 mm
7	1 x Module w = 102 mm h = 116 mm L = 356 mm		 w = 102 mm h = 116 mm	 L = 356 mm h = 116	 w = 102 mm L = 356 mm
	2 x Modules w = 204 mm h = 116 mm L = 356 mm		 w = 204 mm h = 116 mm	 L = 356 mm h = 116	 w = 204 mm L = 356 mm
	3 x Modules w = 306 mm h = 116 mm L = 356 mm		 w = 306 mm h = 116 mm	 L = 356 mm h = 116	 w = 306 mm L = 356 mm
	4 x Modules w = 408 mm h = 116 mm L = 356 mm		 w = 408 mm h = 116 mm	 L = 356 mm h = 116	 w = 408 mm L = 356 mm
	5 x Modules w = 510 mm h = 116 mm L = 356 mm		 w = 510 mm h = 116 mm	 L = 356 mm h = 116	 w = 510 mm L = 356 mm
9	1 x Module w = 102 mm h = 116 mm L = 356 mm		 w = 102 mm h = 116 mm	 L = 356 mm h = 116	 w = 102 mm L = 356 mm
	2 x Modules w = 204 mm h = 116 mm L = 356 mm		 w = 204 mm h = 116 mm	 L = 356 mm h = 116	 w = 204 mm L = 356 mm
	3 x Modules w = 306 mm h = 116 mm L = 356 mm		 w = 306 mm h = 116 mm	 L = 356 mm h = 116	 w = 306 mm L = 356 mm
	4 x Modules w = 408 mm h = 116 mm L = 356 mm		 w = 408 mm h = 116 mm	 L = 356 mm h = 116	 w = 408 mm L = 356 mm
	5 x Modules w = 510 mm h = 116 mm L = 356 mm	 + 50mm thick Coated Batt + Intumescent Sealant	 w = 510 mm h = 116 mm	 L = 356 mm h = 116	 w = 510 mm L = 356 mm

Seal Type	Number of Pathway(s) Series 33	System	Front view	Side view	Top view
<b>6</b>	1 x Module w = 102 mm h = 116 mm L = 356 mm		 w = 102 mm h = 116 mm	 L = 356mm h = 116	 w = 102mm L = 356mm
	1 x Module w = 102 mm h = 116 mm L = 356 mm		 w = 102 mm h = 116 mm	 L = 356mm h = 116	 w = 102mm L = 356mm
<b>8</b>	2 x Modules w = 204 mm h = 116 mm L = 356 mm		 w = 204 mm h = 116 mm	 L = 356mm h = 116	 w = 204mm L = 356mm
	3 x Modules w = 306 mm h = 116 mm L = 356 mm		 w = 306 mm h = 116 mm	 L = 356mm h = 116	 w = 306mm L = 356mm
	4 x Modules w = 408 mm h = 116 mm L = 356 mm		 w = 408 mm h = 116 mm	 L = 356mm h = 116	 w = 408mm L = 356mm
	5 x Modules w = 510 mm h = 116 mm L = 356 mm		 w = 510 mm h = 116 mm	 L = 356mm h = 116	 w = 510mm L = 356mm
	6 x Modules w = 612 mm h = 116 mm L = 356 mm		 w = 612 mm h = 116 mm	 L = 356mm h = 116	 w = 612mm L = 356mm

Seal Type		System	Top view	Side view	Front view
12	1 x Module		 w = 102 mm h = 116 mm	 L = 356mm h = 116	 w = 102mm L = 356mm
	2 x Modules		 w = 204 mm h = 116 mm	 L = 356mm h = 116	 w = 204mm L = 356mm
	3 x Modules		 w = 306 mm h = 116 mm	 L = 356mm h = 116	 w = 306mm L = 356mm
	4 x Modules		 w = 408 mm h = 116 mm	 L = 356mm h = 116	 w = 408mm L = 356mm
	5 x Modules		 w = 510 mm h = 116 mm	 L = 356mm h = 116	 w = 510mm L = 356mm
14	1 x Module		 w = 102 mm h = 116 mm	 L = 356mm h = 116	 w = 102mm L = 356mm
	2 x Modules		 w = 204 mm h = 116 mm	 L = 356mm h = 116	 w = 204mm L = 356mm
	3 x Modules		 w = 306 mm h = 116 mm	 L = 356mm h = 116	 w = 306mm L = 356mm
	4 x Modules	 + 	 w = 408 mm h = 116 mm	 L = 356mm h = 116	 w = 408mm L = 356mm
	5 x Modules	 + 	 w = 510 mm h = 116 mm	 L = 356mm h = 116	 w = 510mm L = 356mm

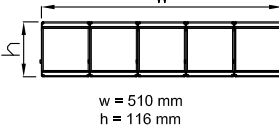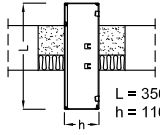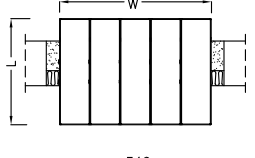Seal Type		System	Top view	Side view	Front view
<b>13</b>	1 x Module w = 102 mm h = 116 mm L = 356 mm		 w = 102 mm h = 116 mm	 L = 356mm h = 116mm	 w = 102mm L = 356mm
<b>15</b>	4 x Modules w = 408 mm h = 116 mm L = 356 mm		 w = 408 mm h = 116 mm	 L = 356mm h = 116mm	 w = 408mm L = 356mm
<b>16</b>	8 x Modules w = 408 mm h = 116 mm L = 356 mm		 w = 408 mm h = 116 mm + w = 408 mm h = 116 mm	 L = 356mm h = 116mm	 w = 408mm L = 356mm + w = 408mm L = 356mm