
 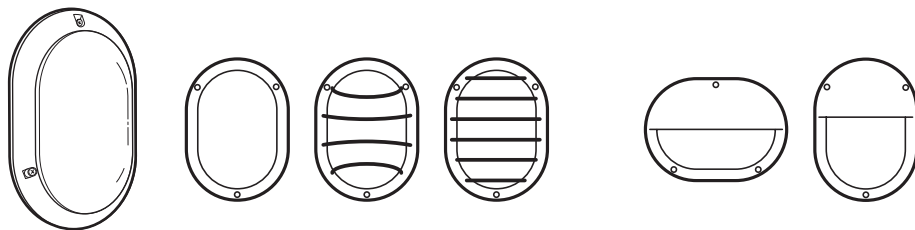



sarlam

CHARTRES


 www.sarlam.com




					
 max	60 W			60 W	
 max	53 W			53 W	
 max	17 W				
 max		13 W / 18 W			

 


< 15 mm

 


> 15 mm → OK

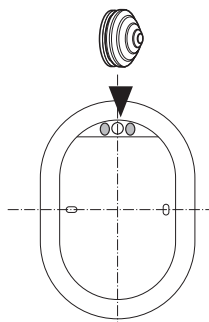



1

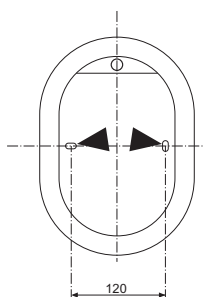

IP 54


 


2

 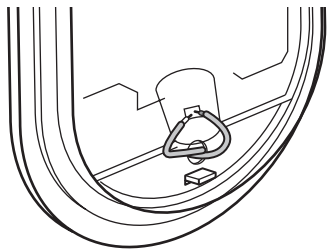


Ø 5 min.
16 max.

50 mm
110 max.

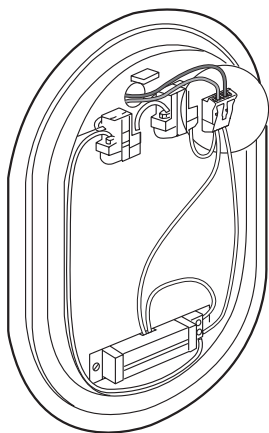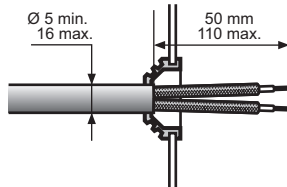


N L1

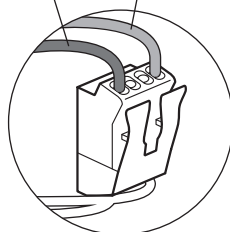


3

1

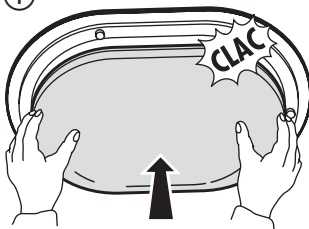

2

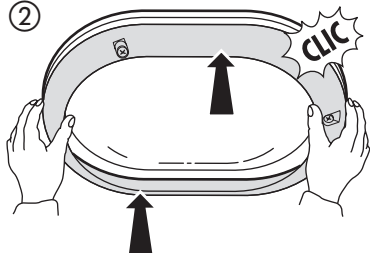

3

