
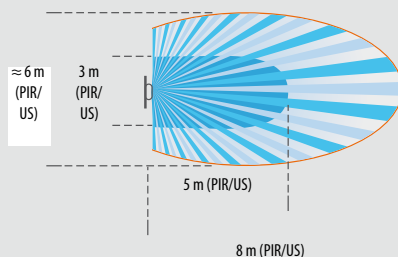


MyHOME® domotique - BUS



automatisme - détecteurs de mouvements

Zones de détection

Réf. HD/HC/HS4658 - 5740 48/98

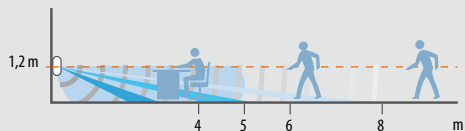


Réf. BMSE2006

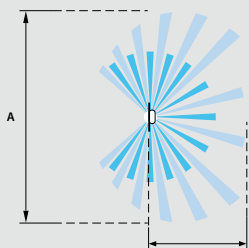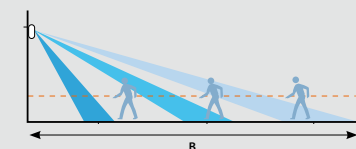

		Sensibilité (25%)			Sensibilité (50%)		
Hauteur (m)		A	B	Surface (m ²)	A	B	Surface (m ²)
		2,5	8	3	66	15	5
3	8	3	66	15	5	131	
4	8	2	58	15	5	116	
5	8	2	53	15	4	105	
6	8	2	47	15	4	94	

		Sensibilité (75%)			Sensibilité (100%)		
Hauteur (m)		A	B	Surface (m ²)	A	B	Surface (m ²)
		2,5	23	8	197	30	10
3	23	8	197	30	10	263	
4	23	7	174	30	9	233	
5	23	6	158	30	8	210	
6	23	5	141	30	7	188	


Réf. BMSE3001

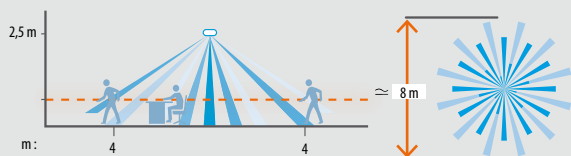

		Sensibilité							
A (m)		Basse		Moyenne		Haute		Maximum	
		Ø (m)	S (m ²)	Ø (m)	S (m ²)	Ø (m)	S (m ²)	Ø (m)	S (m ²)
2,5		4	15	6	25	6,5	30	8	50
3		5,5	25	6,5	35	8,5	60	11,5	100
4		6,5	35	7,5	45	12,5	125	14	155
5		6	30	10,5	90	12	115	16,5	215
6		4	15	5,5	25	8,5	60	12,5	125

Légende :
 A = Hauteur (Installation) (m)
 Ø = Diamètre (m)
 S = Surface (m²)

Réf. BMSE3003

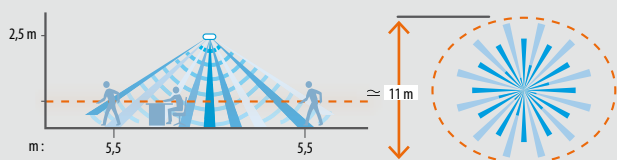

		Sensibilité							
A (m)	Tech.	Basse		Moyenne		Haute		Maximum	
		Ø (m)	S (m ²)	Ø (m)	S (m ²)	Ø (m)	S (m ²)	Ø (m)	S (m ²)
2,5	PIR	4	15	6	25	6,5	30	8	50
	US	4	15	4	15	6	30	11	95
3	PIR	5,5	25	6,5	35	8,5	60	11,5	100
	US	6	30	6	60	8	50	13	150
4	PIR	6,5	35	7,5	45	12,5	125	14	155
	US	6	30	6	30	10	80	13	150
5	PIR	6	30	10,5	90	12	115	16,5	215
	US	6	30	6	30	10	80	13	130
6	PIR	4	15	5,5	25	8,5	60	12,5	125
	US	-	-	6	30	10	80	13	130

Légende :
 A = Hauteur (Installation) (m)
 Ø = Diamètre (m)
 S = Surface (m²)