

XL³ S 160 - 24 modules per row

“ready to use” metal distribution cabinets



3 372 04



3 372 24



Technical characteristics **p. 7**

Cabinets supplied with rails fitted (150 mm fixing centres) and full height faceplates

Doors and terminal blocks to be ordered separately

Take DPX³ 160 and modular protection devices

Used to create assemblies certified IEC 61439-2 and -3

IP 40 with door

IP 30 without door

Cut-outs in top and bottom for feeding cables through

Can take Lina 25 ducting

Pack Cat.No Surface mounting 24-module cabinets

Pack	Cat.No	Number of rows	Number of modules	Height (mm)	Width (mm)	Depth (mm)	Faceplates and body: RAL 9003
1	3 372 02	2	48	440	595	135	200 200
1	3 372 03	3	72	590	595	135	200 150 200
1	3 372 04	4	96	740	595	135	200 150 150 200
1	3 372 05	5	120	890	595	135	200 150 150 150 200
1	3 372 06	6	144	1040	595	135	200 150 150 150 150 200
1	3 372 07	7	168	1190	595	135	200 150 150 150 150 150 200
1	3 372 08	8	192	1340	595	135	200 150 150 150 150 150 150 200

Pack Cat.No Flush-mounting 24-module cabinets

Pack	Cat.No	Number of rows	Number of modules	Height (mm)	Width (mm)	Depth (mm)	Supplied with fixing lugs Faceplates: RAL 9003
1	3 372 22	2	48	512	667	138	200 200
1	3 372 23	3	72	662	667	138	200 150 200
1	3 372 24	4	96	812	667	138	200 150 150 200
1	3 372 25	5	120	962	667	138	200 150 150 150 200
1	3 372 26	6	144	1112	667	138	200 150 150 150 150 200
1	3 372 27	7	168	1262	667	138	200 150 150 150 150 150 200
1	3 372 28	8	192	1412	667	138	200 150 150 150 150 150 150 200

XL³ S 160 - 36 modules per row

“ready to use” metal distribution cabinets



3 372 14



3 372 34

Technical characteristics p. 7

Cabinets supplied with rails fitted (150 mm fixing centres) and full height faceplates
 Doors and terminal blocks to be ordered separately
 Take DPX³ 160 and modular protection devices
 Used to create assemblies certified IEC 61439-2 and -3
 IP 40 with door
 IP 30 without door
 Cut-outs in top and bottom for feeding cables through
 Can take Lina 25 ducting

Surface mounting 36-module cabinets

Pack	Cat.No	Number of rows	Number of modules	Height (mm)	Width (mm)	Depth (mm)	Faceplates and body: RAL 9003
1	3 372 14	4	144	740	810	135	
1	3 372 15	5	180	890	810	135	
1	3 372 16	6	216	1040	810	135	
1	3 372 17	7	252	1190	810	135	
1	3 372 18	8	288	1340	810	135	

Flush-mounting 36-module cabinets

Pack	Cat.No	Number of rows	Number of modules	Height (mm)	Width (mm)	Depth (mm)	Supplied with fixing lugs Faceplates: RAL 9003
1	3 372 34	4	144	812	883	138	
1	3 372 35	5	180	962	883	138	
1	3 372 36	6	216	1112	883	138	
1	3 372 37	7	252	1262	883	138	
1	3 372 38	8	288	1412	883	138	

XL³ S 160

equipment and accessories



3 372 54



3 372 64



3 372 74



3 372 84



0 203 99


Pack	Cat.No	Metal doors
		Supplied with handle Cat.No 3 397 10
		For cabinets with 24 modules per row
		For cabinet (no. of modules)
1	3 372 52	2 x 24
1	3 372 53	3 x 24
1	3 372 54	4 x 24
1	3 372 55	5 x 24
1	3 372 56	6 x 24
1	3 372 57	7 x 24
1	3 372 58	8 x 24
		For cabinets with 36 modules per row
1	3 372 64	4 x 36
1	3 372 65	5 x 36
1	3 372 66	6 x 36
1	3 372 67	7 x 36
1	3 372 68	8 x 36
		Glass doors
		For cabinets with 24 modules per row
		For cabinet (no. of modules)
1	3 372 72	2 x 24
1	3 372 73	3 x 24
1	3 372 74	4 x 24
1	3 372 75	5 x 24
1	3 372 76	6 x 24
1	3 372 77	7 x 24
1	3 372 78	8 x 24
		For cabinets with 36 modules per row
1	3 372 84	4 x 36
1	3 372 85	5 x 36
1	3 372 86	6 x 36
1	3 372 87	7 x 36
1	3 372 88	8 x 36
		Replacement handle for doors
1	3 397 10	Handle for XL ³ S 160 door
1	3 397 15	Locking handle no. 405 Supplied with a set of 2 keys
		Accessories
		Joining kit
1	3 374 04	For connecting two XL ³ S 160 cabinets vertically
		Wall mounting lugs
1	3 374 00	Set of 4 lugs for wall mounting
		Fixing plate and faceplate for DPX³ 160
1	3 374 10	For XL ³ S 160 cabinets with 24 modules per row
1	3 374 11	For XL ³ S 160 cabinets with 36 modules per row

Pack	Cat.No	Self-adhesive document holders for plans
		Open - RAL 7035
		External dimensions
		Height (mm) Width (mm)
20	0 365 80	235 340
20	0 365 81	165 260
		Internal dimensions
		Height (mm) Width (mm) Depth (mm)
		200 310 18
		130 230 18
		Closed - RAL 7035
		Rigid, plastic, IP 50
		Internal dimensions: 324 x 120 x 18 mm
		Transparent
		Soft plastic, A4 - 305 x 220 mm
10	0 097 99	
		Rail height spacer
1	3 382 40	Used to combine modular devices and DPX ³ 160/250 on the same rail
1	3 382 41	Used to combine modular devices and DRX on the same rail
1	3 382 42	Used to combine DRX and DPX ³ 160/250 on the same rail
		White RAL 9003 blanking plates
20	0 016 60	5 modules. Separable into modules or half-modules
20	3 397 54	24 modules, untapped blanking panel which can be cut as required
		Clip-on holders for self-adhesive labels
		Supplied with sheet of labels for marking rows on faceplate
10	3 397 55	24 modules
10	3 397 56	36 modules
		Connection of protective conductors
		Additional brass bar
		For protective conductor. Fits onto functional uprights using the lugs supplied
1	0 373 01	For 24-module width cabinet
1	3 397 57	For 36-module width cabinet
		Equipotential link conductor
1	0 373 85	Length 350 mm. Cross-section 6 mm ²

XL³ S 160

technical characteristics

■ Dimensions of surface mounting cabinets

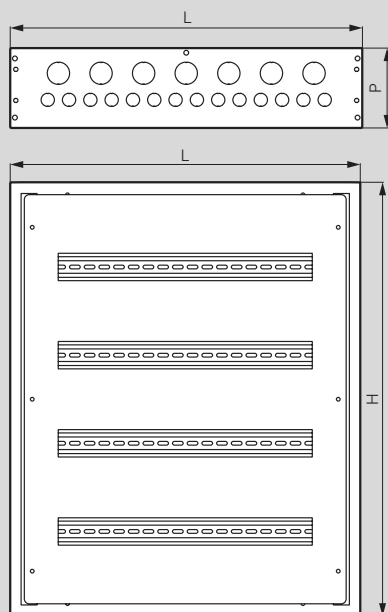


24-module cabinets

Cat.No	H (mm)	W (mm)	D (mm)
3 372 02	440	595	135
3 372 03	590	595	135
3 372 04	740	595	135
3 372 05	890	595	135
3 372 06	1040	595	135
3 372 07	1190	595	135
3 372 08	1340	595	135

36-module cabinets

Cat.No	H (mm)	W (mm)	D (mm)
3 372 14	740	810	135
3 372 15	890	810	135
3 372 16	1040	810	135
3 372 17	1190	810	135
3 372 18	1340	810	135

■ Dimensions of flush-mounting cabinets

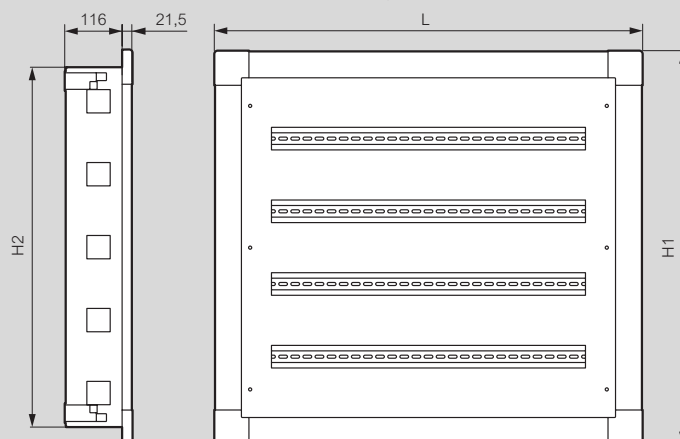

24-module cabinets

Cat.No	H1 (mm)	H2 (mm)	W (mm)
3 372 22	512	440	667
3 372 23	662	590	667
3 372 24	812	740	667
3 372 25	962	890	667
3 372 26	1112	1040	667
3 372 27	1262	1190	667
3 372 28	1412	1340	667

36-module cabinets

Cat.No	H1 (mm)	H2 (mm)	W (mm)
3 372 34	812	740	883
3 372 35	962	890	883
3 372 36	1112	1040	883
3 372 37	1262	1190	883
3 372 38	1412	1340	883